
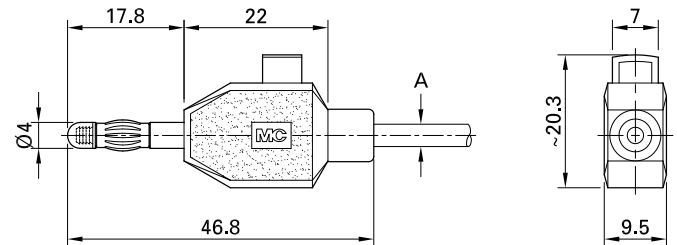


KLS4

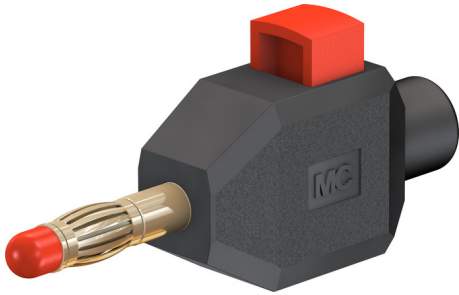

Item number 22.3006-*

Ø 4 mm, with spring-loaded MULTILAM for clamp-connecting stranded wires. Clamp connection.

Technical data

| | |
|--------------------------------------|-----------------------------|
| Diameter of plug system | 4 mm |
| Rated Values | 30 VAC, 10 A / 60 VDC, 10 A |
| Surface treatment electrical contact | Ni |
| Base material electrical contact | CuZn |
| Colours * | 21 22 |
| Outer diameter | 4.8 |
| Test accessory acc. to | IEC EN 61010-031 |