
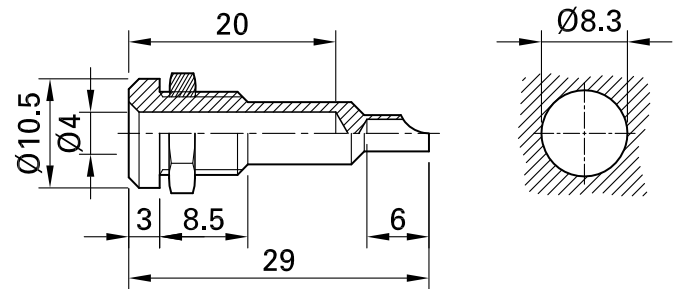


4 MM SOCKET

LB4-R

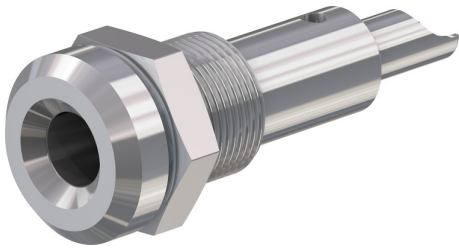

Item number 23.0090

Uninsulated, Ø 4 mm, rigid. Machined brass. The sockets can be screw-mounted in predrilled panels. Solder connection.

Technical data	
Diameter of plug system	4 mm
Rated Values	30 VAC, 40 A / 60 VDC, 40 A
Surface treatment electrical contact	Ni
Base material electrical contact	CuZn
Thread	M8x0,5
Test accessory acc. to	IEC EN 61010-031
Component parts	B-LB4-R; MU/M8x0,5; SP4
Supplied assembly material	MU/M8x0,5; SP4