


PK2-T

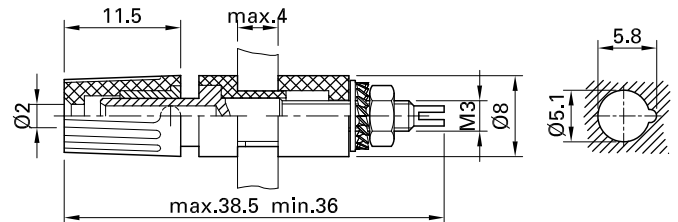

Item number 23.0290-*

Insulated, with Ø 2 mm rigid socket and insulated head undetachable. With Ø 2 mm cross hole for quick wire connection. Machined brass. For mounting, with anti-rotation lug, in frontpanels up to 4 mm thick. Connection: Threaded bolt M3.

Technical data

Diameter of plug system	2 mm
Rated Values	30 VAC, 15 A / 60 VDC, 15 A
Surface treatment electrical contact	Ni
Base material electrical contact	CuZn
Colours *	21 22
Thread	M3
Test accessory acc. to	IEC EN 61010-2-030