


SAB4-G

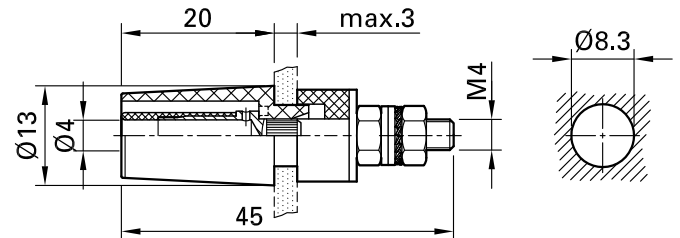

Item number 23.3050-*

Insulated, rigid, Ø 4 mm, accepting spring-loaded Ø 4 mm plugs with rigid insulating sleeve. Machined brass. The socket is surface-mounted in pre-drilled panels of plastic, metal, etc. Connection: Threaded bolt M4.

Technical data	
Diameter of plug system	4 mm
Rated Values	1000 V, CAT II, 32 A
Surface treatment electrical contact	Au
Base material electrical contact	CuZn
Colours *	20 21 22 23 24 25 26 27 28 29
Thread	M4
Test accessory acc. to	IEC EN 61010-2-030
Supplied assembly material	ID-SAB4-G; U/4,3x12; 2x MU0,8D/M4; 2x U/M4; FS/M4
Approvals	UR
Remarks	Accessories: Tube spanner SS2