
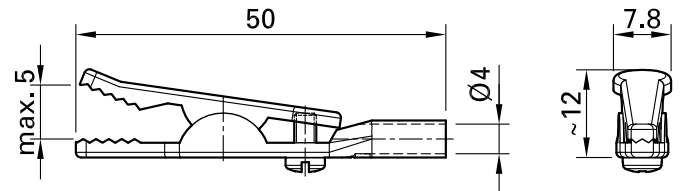


4 MM CLIP

AGK20

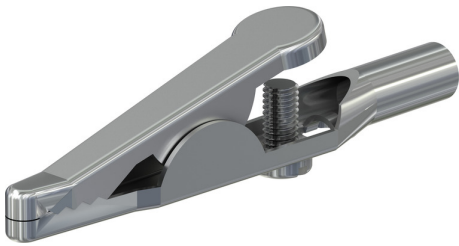

Item number 24.0149

Uninsulated, with \varnothing 4 mm rigid socket. Steel. Connection also possible with screw clamp or soldering.

Technical data	
Diameter of plug system	4 mm
Rated Values	30 VAC, 10 A / 60 VDC, 10 A
Surface treatment electrical contact	Ni
Base material electrical contact	CuZn
Opening width	5.0 mm
Test accessory acc. to	IEC EN 61010-031