


EB4-A/N

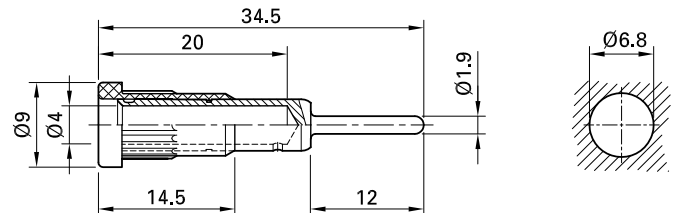

Item number 49.7077-*

Insulated, Ø 4 mm, rigid. Machined brass. The socket is pressed into predrilled panels of plastic, metal etc. Gold-plated version available. Round connecting pin Ø 1.9 mm.

Technical data	
Diameter of plug system	4 mm
Rated Values	30 VAC, 25 A / 60 VDC, 25 A
Surface treatment electrical contact	Ni
Base material electrical contact	CuZn
Colours *	21 22 23 24 25 26 27 29
Test accessory acc. to	IEC EN 61010-2-030
Component parts	I-EB4; B-EB4-A/N
Remarks	Accessories: Press-in Tool MB4