


KS2-12L/N

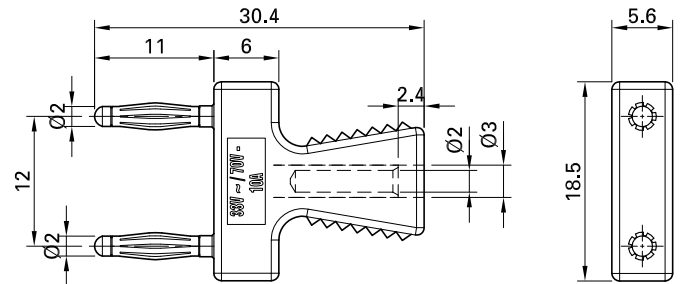

Item number 63.9355-*

Insulated Ø 2 mm jumper plugs with rigid Ø 2 mm socket in handling part. Available in gold-plated version.

| Technical data | |
|--------------------------------------|------------------------------------|
| Diameter of plug system | 2 mm |
| Rated Values | 30 VAC, 10 A / 60 VDC, 10 A |
| Surface treatment electrical contact | Ni |
| Base material electrical contact | CuZn |
| Colours * | 21 22 23 24 25 |
| Plug spacing | 12 mm |
| Suitable for | BL2-12/20/A |
| Test accessory acc. to | IEC EN 61010-031 |
| Remarks | Other colors available on request. |