


## XEG-1R

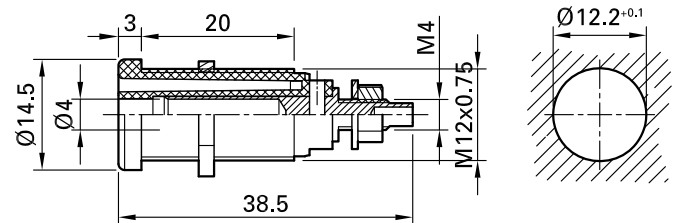

Item number 66.9136-\*

Insulated, rigid, Ø 4 mm, accepting spring-loaded Ø 4 mm plugs with rigid insulating sleeve. Machined brass. The sockets are screwed into pre-drilled panels of plastic, metal, etc. Connection: Threaded bolt M4.

Technical data	
Diameter of plug system	4 mm
Rated Values	1000 V, CAT IV, 20 A
Surface treatment electrical contact	Ni
Base material electrical contact	CuZn
Colours *	<span style="background-color: yellow; border: 1px solid black; padding: 2px;">20</span> <span style="background-color: black; color: white; border: 1px solid black; padding: 2px;">21</span> <span style="background-color: red; color: white; border: 1px solid black; padding: 2px;">22</span> <span style="background-color: blue; color: white; border: 1px solid black; padding: 2px;">23</span>
Thread	M4; M12x0,75
Test accessory acc. to	IEC EN 61010-2-030
Supplied assembly material	GEW.12-MUTTER
Approvals	UR
Remarks	Accessories: Tube spanner SS425