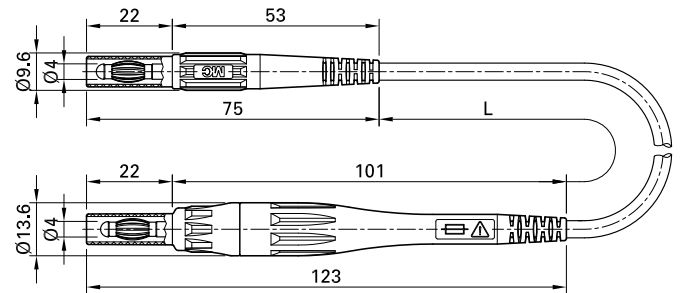


## XSMF-419

Item number 66.9394-\*

Highly flexible, with insulation in PVC. With in-line Ø 4 mm MULTILAM plug with rigid insulating sleeve on both ends. The two-part screw connector accepts a high breaking capacity fuse measuring 6.3 x 32 mm. The fuse is not supplied.

Technical data	
Diameter of plug system	4 mm
Rated Values	1000 V, CAT IV, 8 A
Surface treatment electrical contact	Ni
Base material electrical contact	CuZn
Lead cross section	1.0 mm <sup>2</sup>
Lead lengths <input type="text"/>	100 cm; 150 cm; 200 cm
Lead insulation	PVC
Colours *	<input type="checkbox"/> 21 <input type="checkbox"/> 22 <input type="checkbox"/> 23 <input type="checkbox"/> 24 <input type="checkbox"/> 25 <input type="checkbox"/> 26 <input type="checkbox"/> 27 <input type="checkbox"/> 28
Test accessory acc. to	IEC EN 61010-031
Approvals	UL, CE
Remarks	Accessories: High breaking capacity fuse DMI-0,5A; High breaking capacity fuse DMI-1,6 A