


XLAM-414/SC

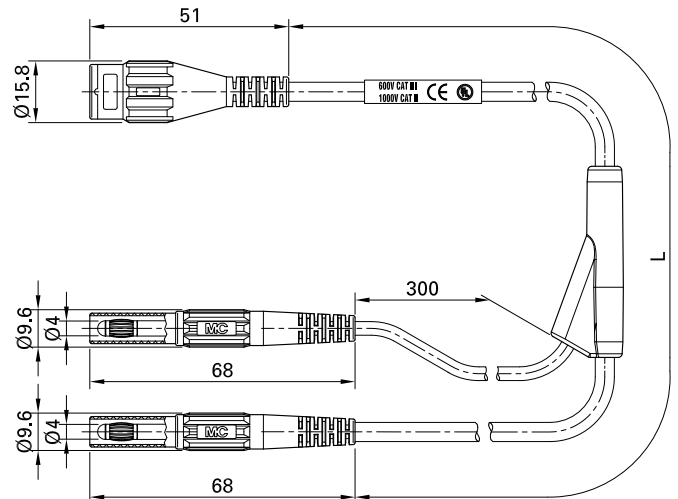

Item number 67.9842-

Highly flexible, fully shielded adapter leads. One end with coaxial cable with touch-protected BNC male connector, other end with in-line Ø 4 mm MULTILAM plugs with rigid insulating sleeve.

Technical data	
Rated Values	600 V, CAT III / 1000 V, CAT II
Temperature range	-10°C ... +70°C
Type coaxial lead	RG58
Connectable coaxial lead: type/diameter	BNC/4 mm
Test accessory acc. to	IEC EN 61010-031
Approvals	UL, CE